

# 1200A Power Distribution Panel

Power Distribution Products



## APPLICATION RANGE

1200A Trystar Vertical Power Distribution Panel


Rated for 600V

## STANDARD FEATURES

- Panel includes 45" Section of Breaker Space
- NEMA 3R All Aluminum Construction
- Changeable Gland Plates
- Heavy Duty Cage with Forklift Pockets
- Metal Casters with Industrial Grade Floor Locks
- Protective Caps on All Panel Mounts to Prevent Accidental Contact
- Made in the USA

## CONFIGURATION

- Input
  - 4 Sets of Male 16 Series Panel Mount Input (BK, RD, BE, WT, GN)
- Output
  - 4X 70-250A 600V Adjustable Breakers
  - 2X 125-400A 600V Adjustable Breakers
  - 6 Sets of Female 16 Series Panel Mount Outputs (BK, RD, BE, WT, GN)

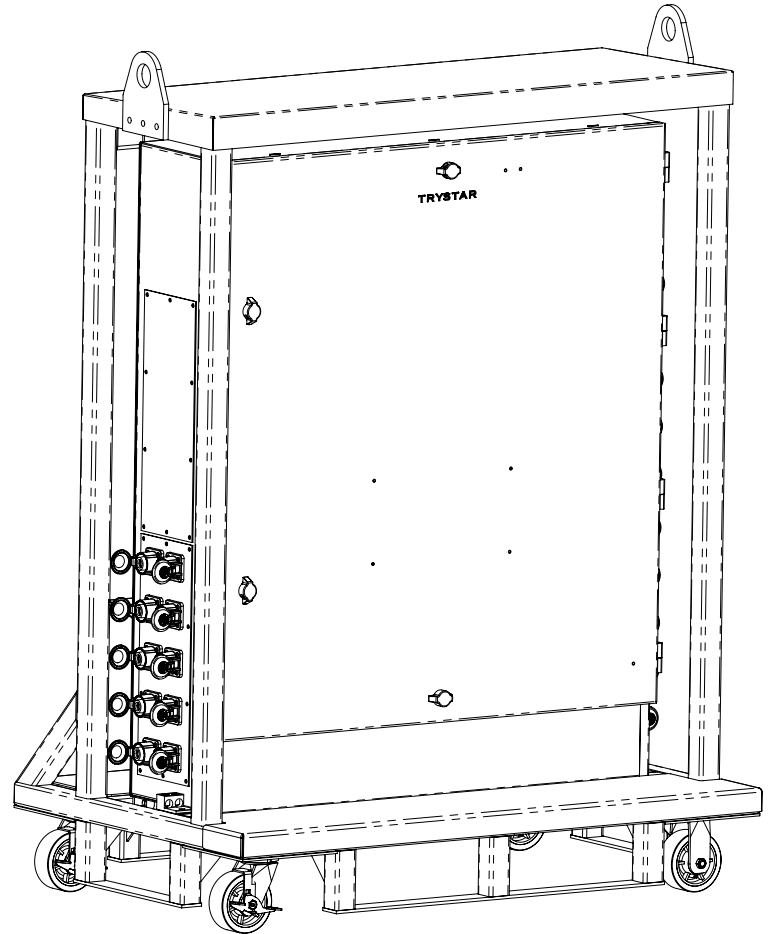

## LISTINGS

- UL1640 Listed
- C(ETL) Listed
- UL 50 Listed
- NEMA 3R


\*Images are representative, specific final design details may vary

# 1200A Power Distribution Panel

## DIMENSIONS AND WEIGHTS



APPROXIMATE WEIGHT: 1,750 LBS.

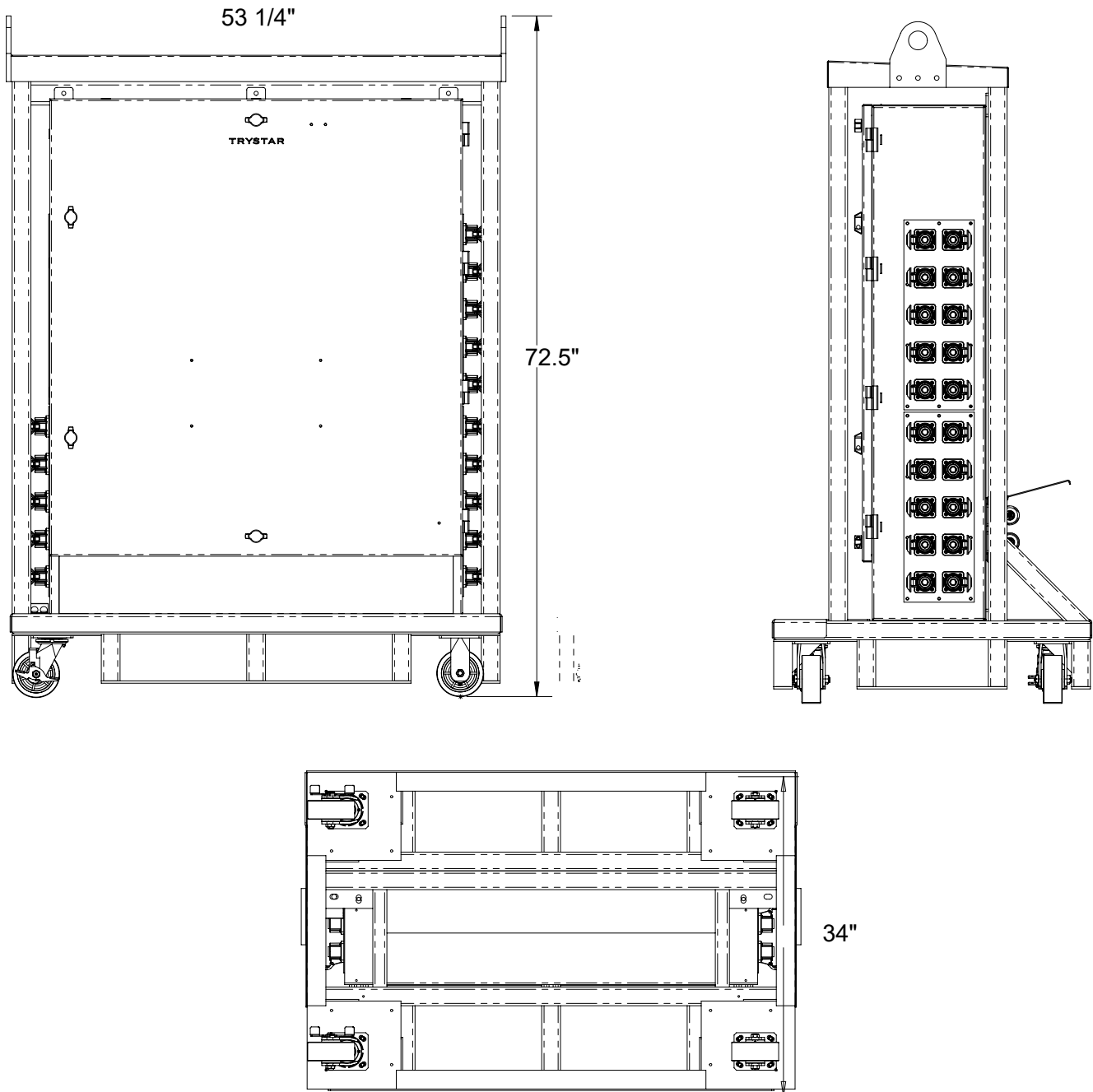

\*Dimensions are representative, specific final design details may vary