

# 1200A Portable ATS

Portable Power Distribution



## APPLICATION RANGE

Trystar Portable Automatic Transfer Switch

1200A 200V-480V

## STANDARD FEATURES

- NEMA 3R All Aluminum Construction
- Open Transition Transfer Switch with LCD Touchscreen Controller
- Touchscreen Dual Voltage Selector
- Initial Start Up Automatic Configuration
- Padlockable Cover Over Input Camlocks
- Mounted Cage with Forklift Pockets and Lifting Eyes
- Auto Start Connections on Source 2
- Clear Protective Flip Lids on All Panel Mounts to Prevent Accidental Contact
- Made in the USA


## CONFIGURATION

- Source 1 Input Connections
  - 3 Set of Male 16 Series Panel Mounts (BK,RD,BE,WT,GN)
- Source 2 Input Connections
  - 3 Set of Male 16 Series Panel Mounts (BK,RD,BE,WT,GN)
- Output Connections
  - 3 Set of Female 16 Series Panel Mounts (BK,RD,BE,WT,GN)

## LISTINGS

- UL1640 Listed
- C(ETL) Listed
- UL 50 Listed
- NEMA 3R

\*Images are representative, specific final design details may vary


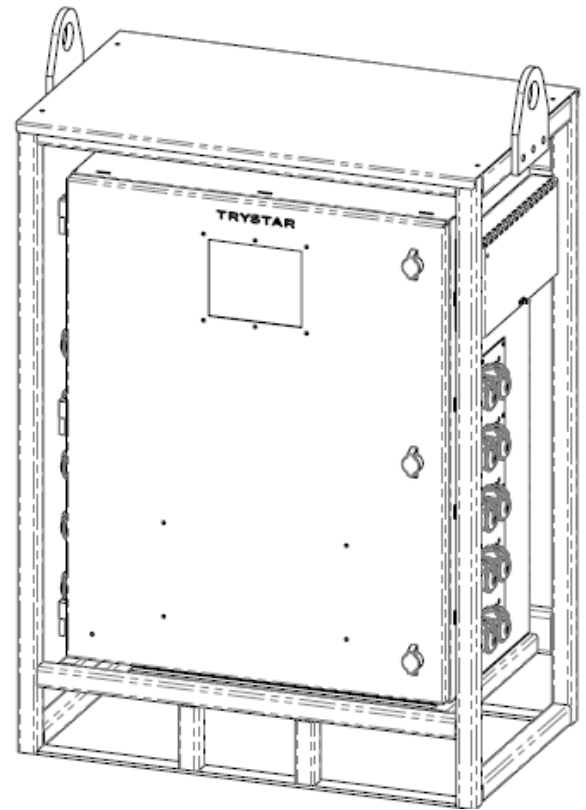


# 1200A Portable ATS

## DIMENSIONS AND WEIGHTS



APPROXIMATE WEIGHT: 230 LBS.

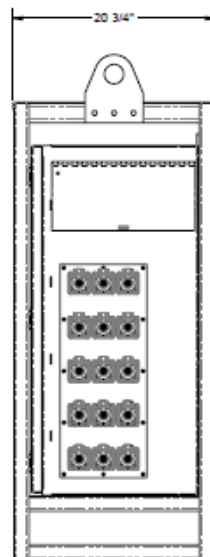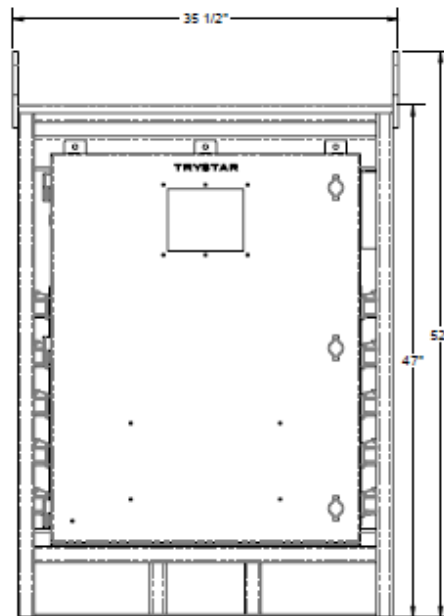

\*Dimensions are representative, specific final design details may vary