

3000A I-LINE

Power Distribution Products



APPLICATION RANGE

3000A Trystar Vertical I-Line

Panel Rated for 600V

STANDARD FEATURES


- I-Line includes 1 x 63" Section of Breaker Space on Left Side of Panel and 2 x 22.5" Sections on the Right Side for a Total of 108"
- NEMA 3R All Aluminum Construction
- Changeable Gland Plates
- Heavy Duty Cage with Forklift Pockets
- Protective Caps on All Panel Mounts to Prevent Accidental Contact
- Made in the USA

CONFIGURATION

- Input
 - 8 Sets of Male 16 Series Panel Mount Input (BK,RD,BE,WT,GN)
- Output
 - Female 16 Series Panel Mount Outputs
 - Hardwire Access through Bottom Conduit Trap Door

LISTINGS


- UL 50 Listed
- NEMA 3R

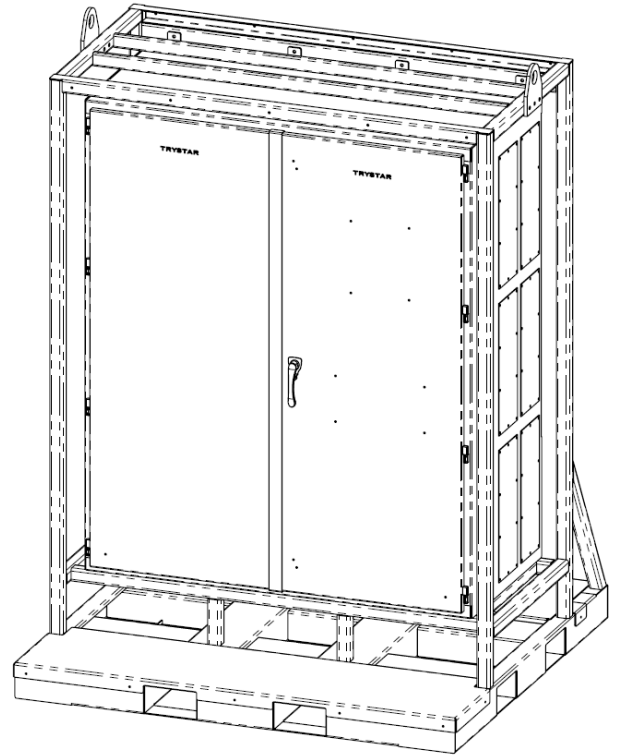

*Images are representative, specific final design details may vary

3000A I-LINE

DIMENSIONS

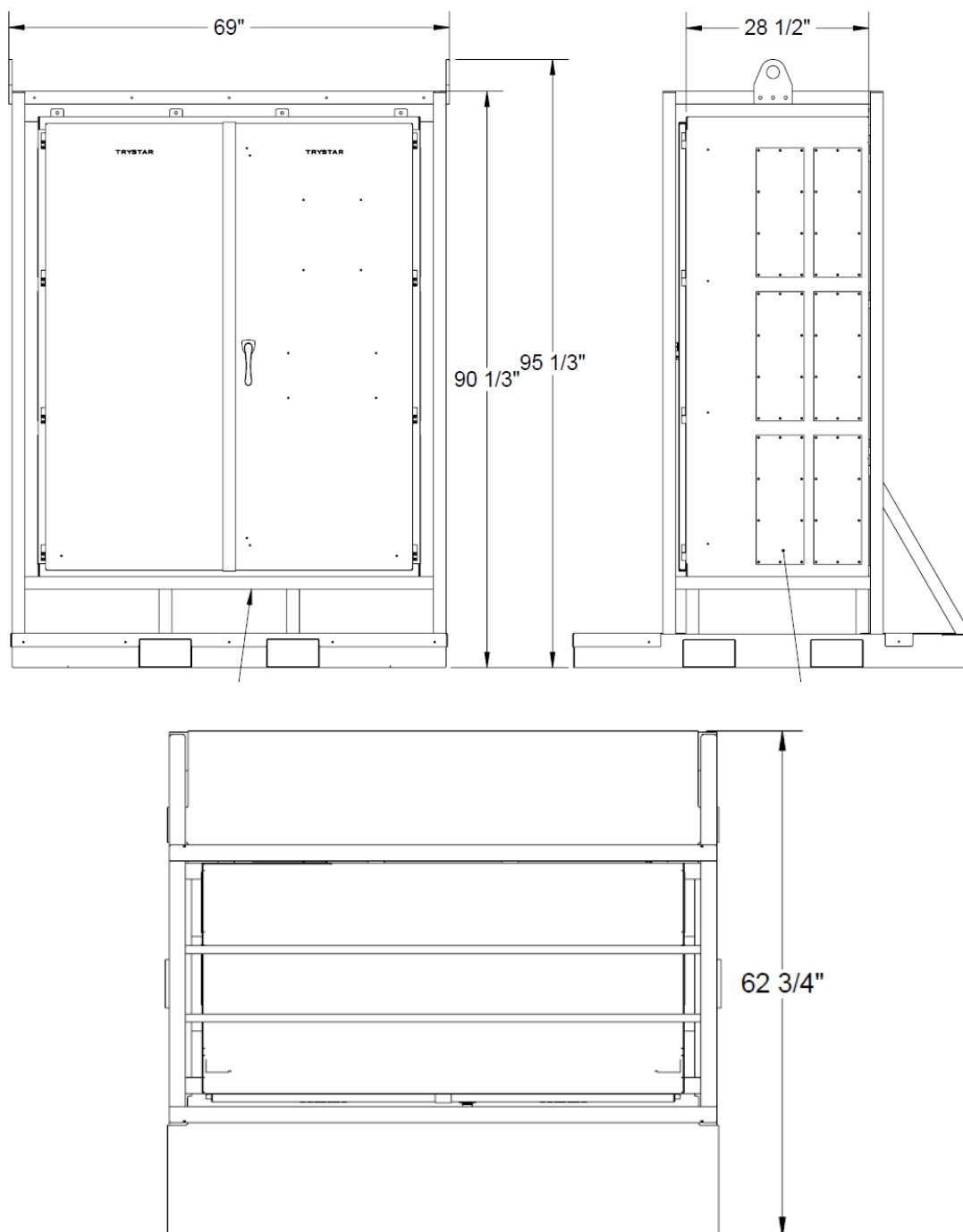

*Dimensions are representative, specific final design details may vary