

600A Portable ATS

Portable Power Distribution



APPLICATION RANGE

Trystar Portable Automatic Transfer Switch

600A 200V-480V

STANDARD FEATURES

- NEMA 3R All Aluminum Construction
- Open Transition Transfer Switch with LCD Touchscreen Controller
- Touchscreen Dual Voltage Selector
- Initial Start Up Automatic Configuration
- Padlockable Cover Over Input Camlocks
- Mounted in Tilt and Roll Cage with Wheels
- Auto Start Connections on Source 2
- Clear Protective Flip Lids on All Panel Mounts to Prevent Accidental Contact
- Made in the USA


CONFIGURATION

- Source 1 Input Connections
 - 2 Set of Male 16 Series Panel Mounts (BK,RD,BE,WT,GN)
- Source 2 Input Connections
 - 2 Set of Male 16 Series Panel Mounts (BK,RD,BE,WT,GN)
- Output Connections
 - 2 Set of Female 16 Series Panel Mounts (BK,RD,BE,WT,GN)

LISTINGS

- UL1640 Listed
- C(ETL) Listed
- UL 50 Listed
- NEMA 3R

*Images are representative, specific final design details may vary


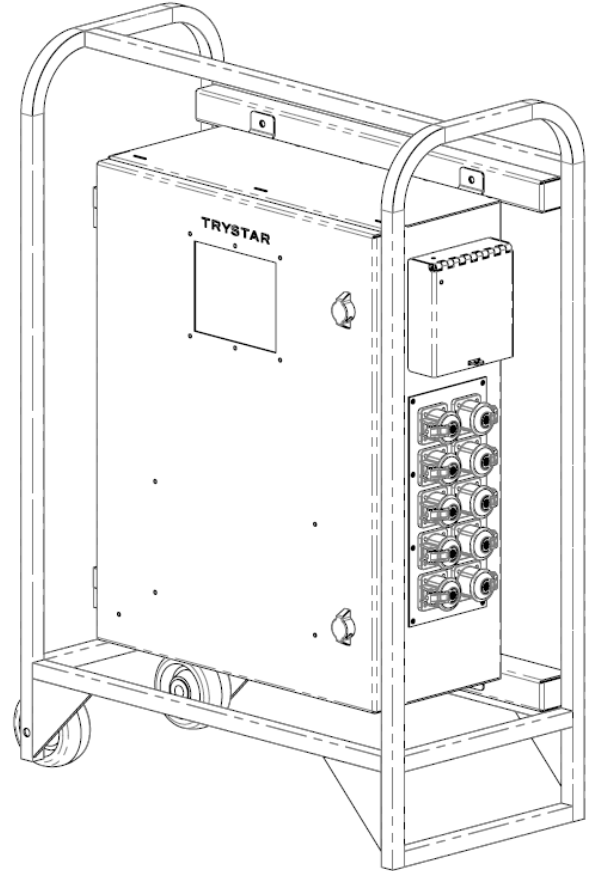


600A Portable ATS

DIMENSIONS AND WEIGHTS



APPROXIMATE WEIGHT: 230 LBS.

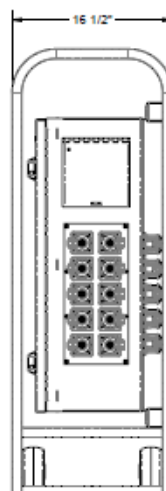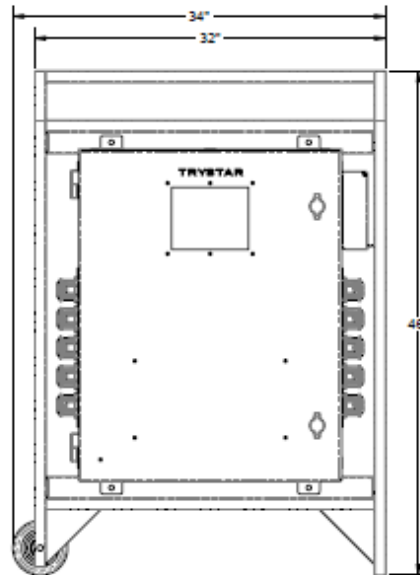

*Dimensions are representative, specific final design details may vary