

Portable EV Charger

Portable Power Distribution



APPLICATION RANGE


Trystar EV Charger 50A 208V

STANDARD FEATURES

- NEMA 3R all aluminum construction
- Heavy-duty stackable legs w/ built-in handles
- Custom powder coat
- Custom UV-printed graphics
- Made in USA

AVAILABLE OPTIONS

- Input
 - 50A California Style Flanged Inlet (125/250V)
- Output
 - 32A EV Charger Controlled with 18FT Extension Cable and Connector
 - 40A Break Protection

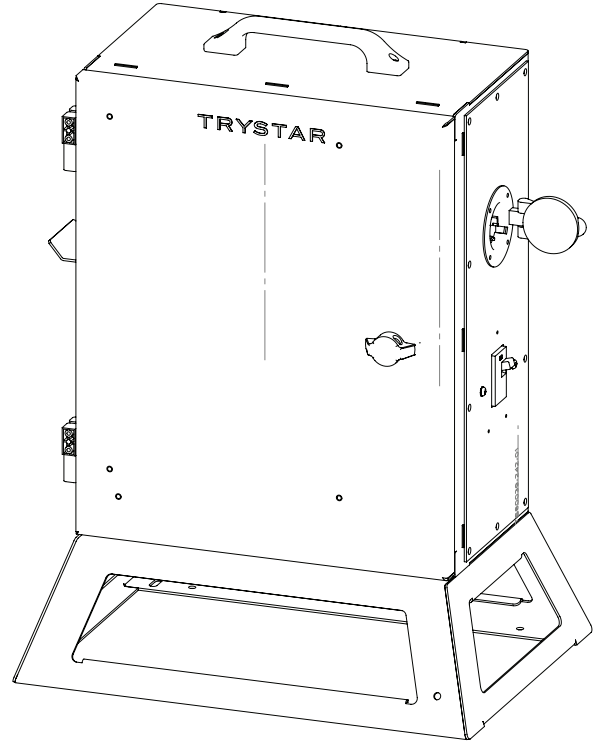


LISTINGS

- UL 50 Listed
- NEMA 3R

*Images are representative, specific final design details may vary

Portable EV Charger

DIMENSIONS

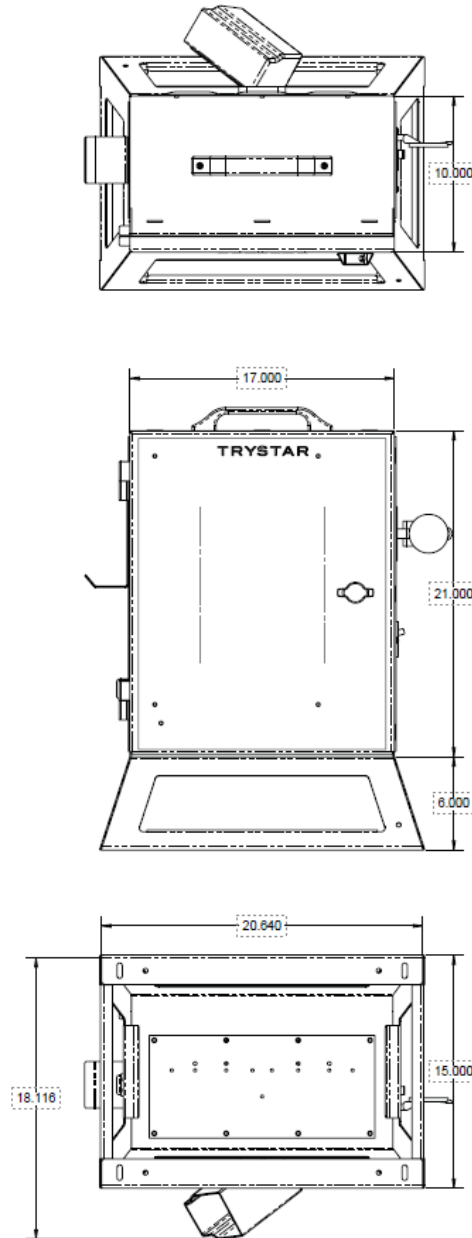

*Dimensions are representative, specific final design details may vary